


SPICE thermal model

PSMN5R3-25MLD

Symbol	Parameter	Conditions	Min	Typ	Max	Unit
$R_{th(j-mb)}$	thermal resistance from junction to mounting base		-	-	2.94	K/W

C_{th1}	1.166E-05 F
C_{th2}	8.652E-05 F
C_{th3}	9.879E-05 F
C_{th4}	5.812E-04 F
C_{th5}	1.314E-03 F
C_{th6}	3.253E-03 F
C_{th7}	7.960E-02 F
C_{th8}	1.396E+02 F
R_{th1}	5.081E-03 Ω
R_{th2}	1.197E-02 Ω
R_{th3}	6.889E-02 Ω
R_{th4}	1.639E-01 Ω
R_{th5}	7.572E-01 Ω
R_{th6}	1.630E+00 Ω
R_{th7}	3.028E-01 Ω
R_{th8}	3.989E-03 Ω

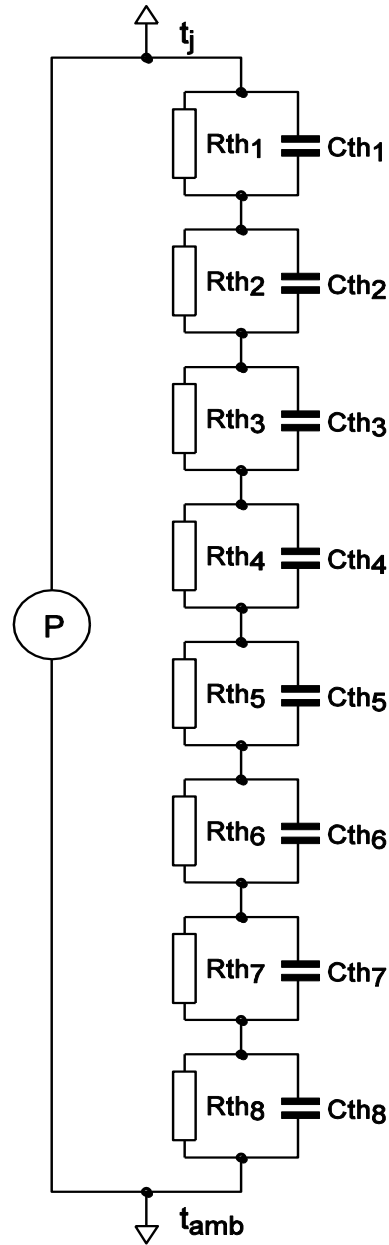

001aal768

Part: PSMN5R3-25MLD
 Date: 22/3/2016
 Model Rth 2.94 K/W